


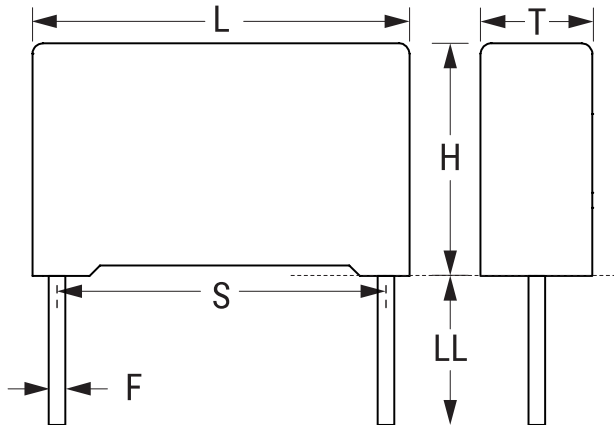

General Information

Series	C24
Dielectric	Metallized Polypropylene
Style	Radial
RoHS	Yes
Lead	Cut
Typical Component Weight	5.88 g
Miscellaneous	Rated current = 0.11A.

Dimensions

L	26.5mm +0.3mm
H	18.5mm +0.1mm
T	10mm +0.2mm
S	22.5mm +/-0.4mm
LL	4mm +2mm
F	0.8mm +/-0.05mm

Specifications

Capacitance	0.7 uF
Tolerance	5%
Voltage AC	400 VAC
Temperature Range	-40/+85°C
Rated Temperature	85°C
Max dV/dt	50 V/us

Packaging Specifications

Packaging	Bulk, Bag
-----------	-----------