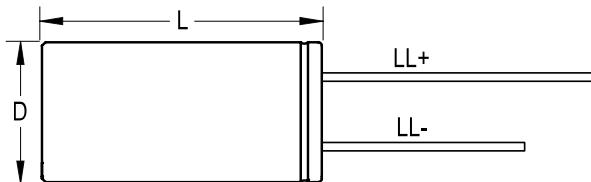
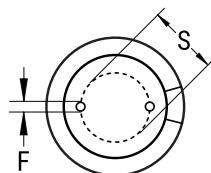


SIDE VIEW

TERMINAL END VIEW

 Click [here](#) for the 3D model.

General Information

类别	ESK
电介质	Aluminum Electrolytic
描述	Single Ended, Aluminum Electrolytic
RoHS	Yes
引线	Wire Leads
AEC-Q200	No

Dimensions

D	6.3mm +/-0.5mm
L	11mm +/-1.5mm
S	2.5mm +/-0.5mm
LL 负极	15mm MIN
LL 正极	20mm MIN
F	0.5mm NOM

Specifications

容值	100 uF
容差	20%
直流电压	35 VDC, 44 VDC (Surge)
温度范围	-40/+85°C
额定温度	85°C
寿命	2000 Hrs
损耗因数	12% 120Hz 20C
电流	185 mAmps (120Hz 85C)
漏电流	35 uA (2min 20°C)
-25°C 阻抗比	3
-40°C 阻抗比	3

Packaging Specifications

包装	Bulk, Bag
----	-----------

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.